

生産終了商品のお知らせ

生産終了商品

多軸モーションコントローラ

3-3437A-00-0000-B100
3-3437A-00-0000-F100
3-3437A-00-A000-F100

推奨代替商品

多軸モーションコントローラ

3-4017A-00-A001-B100
3-4017A-00-A001-F100
3-4017A-00-A001-F100

■最終受注年月

2024年3月末

■最終出荷年月

2024年9月末

■修理対応終了年月

2027年9月末

■推奨代替商品をご利用いただいた場合の注意点

- ・ACC-5Eシリーズ(3-3437A-00-□000-□100)の生産終了のお知らせとなります。
推奨代替商品はACC-5E3シリーズ(3-4017A-00-A001-□100)となります。
- ・プログラムの互換性がないため、プログラミングツールを用いた操作方法が変更となります。

■生産終了商品との相違点

推奨代替商品形式	本体の色	外形寸法	配線接続	取付寸法	定格性能	動作特性	操作方法
3-4017A-00-A001-□100	◎	◎	○	◎	○	○	×

◎：互換

○：ほとんど変更ありません／相似性の高い変更

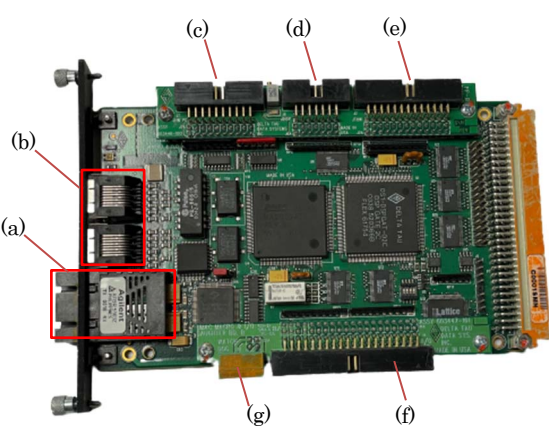
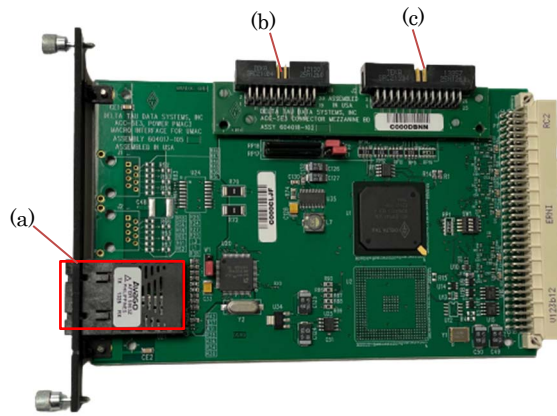
×：変更大

—：該当する仕様がありません

■生産終了商品と推奨代替商品

生産終了商品	推奨代替商品	標準価格(¥)
3-3437A-00-0000-B100	3-4017A-00-A001-B100	オープン価格
3-3437A-00-0000-F100	3-4017A-00-A001-F100	オープン価格
3-3437A-00-A000-F100	3-4017A-00-A001-F100	オープン価格

■端子配置／配線接続

<p>生産終了商品 3-3437A-00-□000-□100</p>	<p>推奨代替商品 3-4017A-00-A001-□100</p>
 <p>(a) 2- MACRO SC-Style ファイバーコネクタ (b) MACRO RJ-45 コネクタ (c) J7 - JHW (ハンドホイールポート、パルス、方向出力の組み合わせ :20ピンボックスヘッダー) (d) J6 - ディスプレイ (e) J2-JTHW (サムホイールポートコネクタ:26ピンボックスヘッダーコネクタ) (f) J4- I/O (g) TB1- Watchdog</p>	 <p>(a) 2- MACRO SC-Style ファイバーコネクタ (b) J1 Top: ハンドホイールポート (c) J2 Top: 汎用I/Oポート</p>

■操作方法

<p>生産終了商品 3-3437A-00-□000-□100</p>	<p>推奨代替商品 3-4017A-00-A001-□100</p>
<p>Turbo UMACシステムとPower UMACシステム両方の環境で動作可能です。</p>	<p>Power UMACシステムにのみ使用可能です。</p>

本案内に記載の仕様・価格は、発行時点のものです。予告なく変更することがありますので、ご了承ください。
 本案内では主に仕様上の変更点を記載しています。ご使用上の注意事項等、ご使用の際に必要な内容につきましては、必ずカタログ、仕様書、取扱説明書、マニュアル等をお読みください。

参考資料:

3-3437A-00-□000-□100 Part Number

UMAC ACC-5E

3	-	3	4	3	7	A	-	0	0	-		0	0	-		1		
---	---	---	---	---	---	---	---	---	---	---	--	---	---	---	--	---	--	--

(E)

(H)

(I)

(K)

(L)

(E)

0 - No MACRO Interface

A - Fiber-Optic MACRO Transceiver

B - Fiber-Optic MACRO Transceiver & RJ-45 MACRO Connector

C - RJ-45 MACRO Connector

MACRO Communication Options

(H)

0 - 16-Node MACRO ASIC

1 - 32-Node MACRO ASIC

MACRO Node Options

(I)

B - BLACK Front, top and bottom plates (Standard)

F - BLACK Front plate only Order as Spare Only

R - SILVER Front, top and bottom plates

A - SILVER Front plate only Order as Spare Only

Plate Options

(K) (L)

00 - No Additional* Options

xx - Factory assigned digits for Additional* Options

Factory Assigned Options

* If Any Additional Option is required, contact factory for digits K and L (Factory Assigned digits).

3-4017A-00-A001-□100 Part Number

UMAC ACC-5E3

3	-	4	0	1	7	A	-	0	0	-		0	0	-		1		
---	---	---	---	---	---	---	---	---	---	---	--	---	---	---	--	---	--	--

(E)

(H)

(I)

(K)

(L)

(E)

A - Fiber-Optic MACRO Transceiver

MACRO Communication Options

(H)

1 - 32-Node MACRO ASIC

2 - 64-Node MACRO ASIC

MACRO Node Options

(I)

B - BLACK Front, top and bottom plates (Standard)

F - BLACK Front plate only Order as Spare Only

Plate Options

(K) (L)

00 - No Additional* Options

xx - Factory assigned digits for Additional* Options

Factory Assigned Options

* If Any Additional Option is required, contact factory for digits K and L (Factory Assigned digits).