

August 1, 2011

Manual

No. 2011229E

The mistake of the print and the description is found in the manual that our company issued. It apologizes.

[Name of catalog]

"DeviceNet Safety DST1 Series Safety I/O Terminals OPERATION MANUAL"

(Publication in March, 2008)

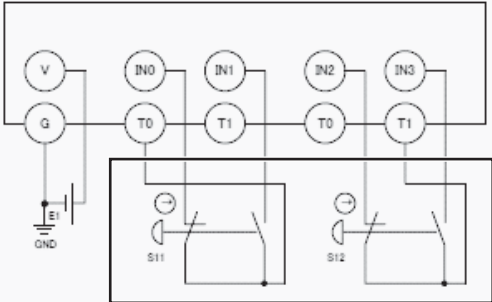
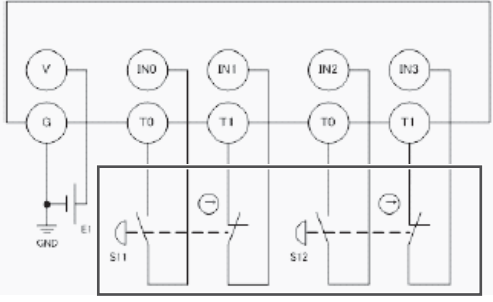
(Catalog number Z904-E1-05) (Catalog number of Japanese Version SJLB-401E)

[Page of publishing]

Page 92 "8-2 Examples of Wiring for Each Application" 8-2-2 Two-Hand Input

(8-4 page in Japanese manual)

[Content of correction]

Before	After
<p>Wiring</p>  <p>E1: 24-V DC Power Supply (S8□□) S11,S12: Two-hand control switches</p>	<p>Wiring</p>  <p>E1: 24-V DC Power Supply (S8□□) S11,S12: Two-hand control switches</p> <p>To connect switches, connect the NO terminals to input 0/2 and NC terminals to input 1/3.</p>

[Correction method]

We revise it at the time of a manual reprint on the next time. (The Revised version will be Rev.06 with the English manual, and Rev. F with the Japanese manual.)

We attach the correction note about this in existing manuals until revised manuals are published.